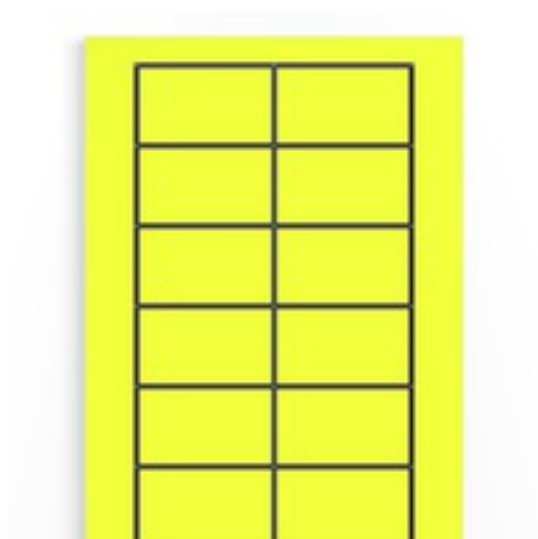


PAGETAB 60/35**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration



PageTab are woven-fabric labels in sheet form. Except for the 8 x 20 version, all labels have a black border.

General ordering data

Version	Device markers, Device markers, 35 x 60 mm, yellow
Order No.	1686220000
Type	PAGETAB 60/35
GTIN (EAN)	4008190492656
Qty.	25 pc(s).

PAGETAB 60/35

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	0.08 mm	Depth (inches)	0.003 inch
Height	35 mm	Height (inches)	1.378 inch
Width	60 mm	Width (inches)	2.362 inch
Net weight	8.88 g		

Temperatures

Operating temperature range	-29...93 °C
-----------------------------	-------------

General data

Adhesive	Permanent acrylic copolymer		
Colour	yellow		
Material	Acrylic-coated fibre webbing		
Material colour according to resistance code	4		
Number of markers per combination	1 Label sheet = 16 Device markers		
Number of markers per packaging unit	400		
Number of markers per packaging unit	Number of markers per combination	16	
	Number of combinations per packaging unit	25	
	Form of supply	Label sheet	
Number per sheet	16		
Operating temperature range	-29...93 °C		
Operating temperature range, max.	93 °C		
Operating temperature range, min.	-29 °C		
Printed characters	without		
Printing	Neutral		
Version	Self-adhesive		
Width	60 mm		

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 9.0	27-40-06-29
ECLASS 9.1	27-40-06-29	ECLASS 10.0	27-40-06-29
ECLASS 11.0	27-28-11-04	ECLASS 12.0	27-28-11-04
ECLASS 13.0	27-28-11-04	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Approvals

ROHS	Conform
------	---------

Downloads

Catalogues	Catalogues in PDF-format
------------	--

