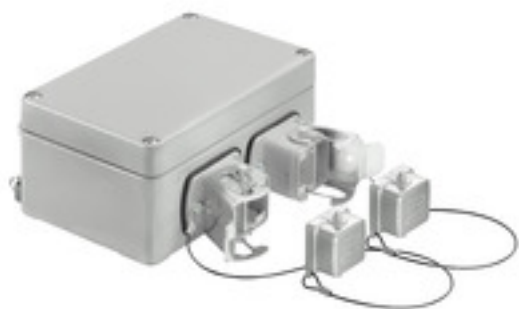


IE-OM-V05M-K21-2S**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

Design for HDC / Rockstar plug-in connectors ver.5 according to IEC 61076-3-106, metal

General ordering data

Version	Junction box, IP67, Variant 5, 2 ports, straight
Order No.	1966290000
Type	IE-OM-V05M-K21-2S
GTIN (EAN)	4032248658480
Qty.	1 pc(s).

IE-OM-V05M-K21-2S

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	57 mm	Depth (inches)	2.244 inch
Width	136 mm	Width (inches)	5.354 inch
Length	125 mm	Length (inches)	4.921 inch
Net weight	643 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Colour	grey	Housing main material	AL-Si 12
Plugging cycles	750	Protection degree	IP67
Type of mounting	Floor-mounted, Wall mounting		

General standards

Connector standard	IEC 61076-3-106 Var. 5
--------------------	------------------------

Classifications

ETIM 7.0	EC002597	ETIM 8.0	EC002597
ETIM 9.0	EC002597	ETIM 10.0	EC002597
ECLASS 9.1	27-44-03-18	ECLASS 10.0	27-44-03-18
ECLASS 11.0	27-44-03-18	ECLASS 12.0	27-44-03-18
ECLASS 13.0	27-44-03-18	ECLASS 14.0	27-44-03-18
ECLASS 15.0	27-44-03-18		

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6bl, 6c
REACH SVHC	Lead 7439-92-1 Potassium perfluorobutane sulfonate 29420-49-3
SCIP	3767b26f-703a-492e-9234-36e83d1c0725

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN


IE-OM-V05M-K21-2S

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

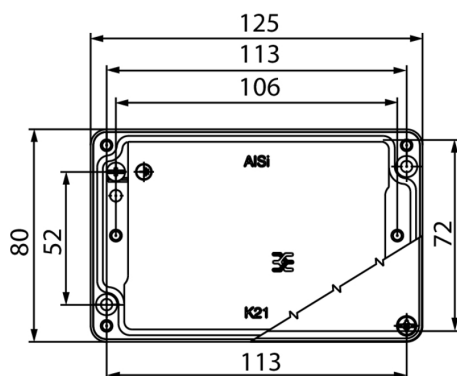

Drawing

