

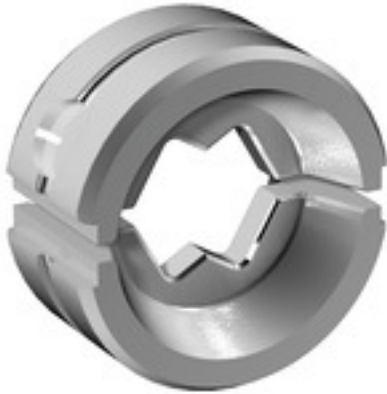
ES EPG/HPG 60 WM 10**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration**Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts**

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

Version	Crimping tool insert, 10mm ² , WM crimp
Order No.	2469540000
Type	ES EPG/HPG 60 WM 10
GTIN (EAN)	4050118483819
Qty.	1 pc(s).

ES EPG/HPG 60 WM 10

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	22 mm	Depth (inches)	0.866 inch
Height	42 mm	Height (inches)	1.654 inch
Width	42 mm	Width (inches)	1.654 inch
Net weight	149 g		

Crimp inserts

Crimp cross-section copper	10	Crimping width	7 mm
Crimping width in mm	7		

Description of contact

Conductor cross-section, max. AWG	8	Conductor cross-section, min. AWG	8
Crimping range, max.	10 mm ²	Type of contact	Euro series cable lug

tool data crimping

Cable lug cross section	nominal	10 mm ²
Crimping type/profile	WM crimp	

Classifications

ETIM 6.0	EC001282	ETIM 7.0	EC001282
ETIM 8.0	EC001282	ETIM 9.0	EC001282
ETIM 10.0	EC001282	ECLASS 9.0	21-04-90-90
ECLASS 9.1	21-01-90-90	ECLASS 10.0	21-04-90-90
ECLASS 11.0	21-04-90-90	ECLASS 12.0	21-04-90-90
ECLASS 13.0	21-04-90-90	ECLASS 14.0	21-04-90-90
ECLASS 15.0	21-04-90-90		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Downloads

Catalogues	Catalogues in PDF-format
------------	--

ES EPG/HPG 60 WM 10

Weidmüller Interface GmbH & Co. KG

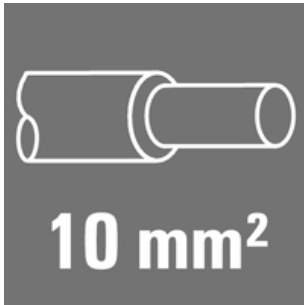
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

10 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KQN-M5/-10	Version
Order No.	1494020000	cable lug, terminal end, 10 mm ²
GTIN (EAN)	4050118303681	
Qty.	100 pc(s).	
Type	KQN-M10/-10	Version
Order No.	1494050000	cable lug, terminal end, 10 mm ²
GTIN (EAN)	4050118303711	
Qty.	100 pc(s).	
Type	KQN-M6/-10	Version
Order No.	1494030000	cable lug, terminal end, 10 mm ²
GTIN (EAN)	4050118303483	
Qty.	100 pc(s).	
Type	KQN-M8/-10	Version
Order No.	1494040000	cable lug, terminal end, 10 mm ²
GTIN (EAN)	4050118303803	
Qty.	100 pc(s).	
Type	KQN-M12/-10	Version
Order No.	1494060000	cable lug, terminal end, 10 mm ²
GTIN (EAN)	4050118304008	
Qty.	100 pc(s).	
Type	KQN-M4/-10	Version
Order No.	1494010000	cable lug, terminal end, 10 mm ²
GTIN (EAN)	4050118303810	
Qty.	100 pc(s).	

ES EPG/HPG 60 WM 10

Weidmüller Interface GmbH & Co. KG

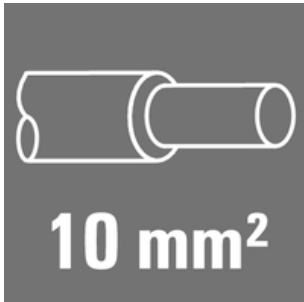
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

10 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VSTN/-10	Version
Order No.	1497130000	cable lug, terminal end, 10 mm ² , 10 mm ² , None
GTIN (EAN)	4050118306491	
Qty.	50 pc(s).	

10 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KQNG-M6/-10	Version
Order No.	1492690000	cable lug, terminal end, 10 mm ² , 10 mm ²
GTIN (EAN)	4050118302394	
Qty.	100 pc(s).	

Type	KQNG-M5/-10	Version
Order No.	1492680000	cable lug, terminal end, 10 mm ² , 10 mm ²
GTIN (EAN)	4050118302479	
Qty.	100 pc(s).	

ES EPG/HPG 60 WM 10

Weidmüller Interface GmbH & Co. KG

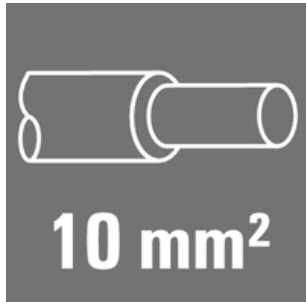
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

10 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KWPN-M6/-10 90	Version
Order No.	1497420000	cable lug, terminal end, 10 mm ²
GTIN (EAN)	4050118307023	
Qty.	100 pc(s).	
Type	KWPN-M8/-10 90	Version
Order No.	1497430000	cable lug, terminal end, 10 mm ²
GTIN (EAN)	4050118306927	
Qty.	100 pc(s).	

Tools



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

Type	EPG 60	Version
Order No.	2453810000	Pressing tools, Tools, Pressing tool, 6mm ² , 300mm ² , Hexagonal crimp,
GTIN (EAN)	4050118468434	WM crimp, Indent crimp, Trapezoidal crimp, Oval crimping
Qty.	1 pc(s).	

ES EPG/HPG 60 WM 10

Weidmüller Interface GmbH & Co. KG

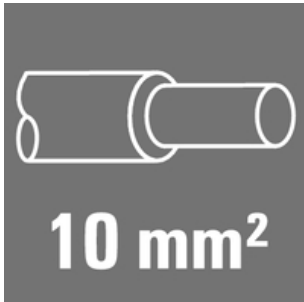
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

10 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KWN-M10/-10 90	Version
Order No.	1497050000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306750	
Qty.	100 pc(s).	
Type	KWN-M12/-10 90	Version
Order No.	1497070000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306606	
Qty.	100 pc(s).	
Type	KWN-M5/-10 90	Version
Order No.	1497020000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306712	
Qty.	100 pc(s).	
Type	KWN-M6/-10 90	Version
Order No.	1497030000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306484	
Qty.	100 pc(s).	
Type	KWN-M8/-10 90	Version
Order No.	1497040000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306576	
Qty.	100 pc(s).	

ES EPG/HPG 60 WM 10

Weidmüller Interface GmbH & Co. KG

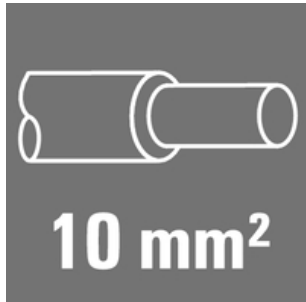
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

10 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VPN/-10	Version
Order No.	1498620000	cable lug, terminal end, 10 mm ² , 10 mm ² , None
GTIN (EAN)	4050118308136	
Qty.	100 pc(s).	

10 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KWN-M8/-10 45	Version
Order No.	1496830000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306330	
Qty.	100 pc(s).	
Type	KWN-M5/-10 45	Version
Order No.	1496810000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306309	
Qty.	100 pc(s).	
Type	KWN-M6/-10 45	Version
Order No.	1496820000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306286	
Qty.	100 pc(s).	
Type	KWN-M10/-10 45	Version
Order No.	1496840000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306361	
Qty.	100 pc(s).	

ES EPG/HPG 60 WM 10

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Tools



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 400 mm²
- 360° revolving quick action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- Additional features for APG series:
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB

General ordering data

Type	HPG 60	Version
Order No.	2453820000	6mm ² , 300mm ² , Hexagonal crimp, WM crimp, Indent crimp,
GTIN (EAN)	4050118468427	Trapezoidal crimp, Oval crimping
Qty.	1 pc(s).	

10 mm²



The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VSTN/10	Version
Order No.	1493030000	cable lug, terminal end, 10 mm ² , 10 mm ² , None
GTIN (EAN)	4050118302776	
Qty.	100 pc(s).	

ES EPG/HPG 60 WM 10

Weidmüller Interface GmbH & Co. KG

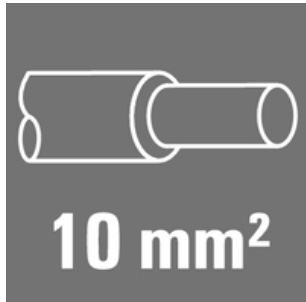
Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

10 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KSN/-10	Version
Order No.	1492780000	cable lug, terminal end, 10 mm ² , 10 mm ²
GTIN (EAN)	4050118302806	
Qty.	100 pc(s).	

10 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KRN-M5/-10	Version
Order No.	1496910000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306378	
Qty.	100 pc(s).	
Type	KRN-M6/-10	Version
Order No.	1496920000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306439	
Qty.	100 pc(s).	
Type	KRN-M8/-10	Version
Order No.	1496930000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306552	
Qty.	100 pc(s).	
Type	KRN-M10/-10	Version
Order No.	1496940000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306521	
Qty.	100 pc(s).	

ES EPG/HPG 60 WM 10

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

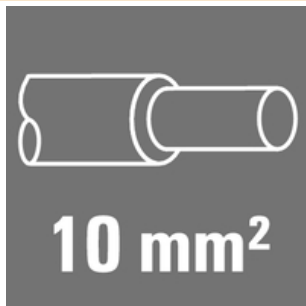
D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	KRN-M4/-10	Version
Order No.	1496900000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306293	
Qty.	100 pc(s).	
Type	KRN-M12/-10	Version
Order No.	1496950000	cable lug, terminal end, 10 mm ² , 10 mm ² - 10 mm ²
GTIN (EAN)	4050118306453	
Qty.	100 pc(s).	

10 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KP-M10/-10	Version
Order No.	1497910000	cable lug, terminal end, 10 mm ²
GTIN (EAN)	4050118307276	
Qty.	100 pc(s).	
Type	KP-M5/-10	Version
Order No.	1497870000	cable lug, terminal end, 10 mm ²
GTIN (EAN)	4050118307252	
Qty.	100 pc(s).	
Type	KP-M6/-10	Version
Order No.	1497880000	cable lug, terminal end, 10 mm ²
GTIN (EAN)	4050118307283	
Qty.	100 pc(s).	
Type	KP-M8/-10	Version
Order No.	1497890000	cable lug, terminal end, 10 mm ²
GTIN (EAN)	4050118307573	
Qty.	100 pc(s).	

ES EPG/HPG 60 WM 10**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****10 mm²**

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VPLN/-10	Version
Order No.	1492890000	cable lug, terminal end, 10 mm ² , 10 mm ² , None
GTIN (EAN)	4050118302561	
Qty.	100 pc(s).	