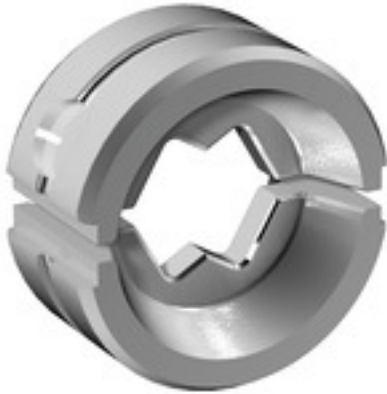


ES EPG/HPG 60 WM 240**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration****Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts**

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

Version	Crimping tool insert, 240mm ² , WM crimp
Order No.	2469640000
Type	ES EPG/HPG 60 WM 240
GTIN (EAN)	4050118484052
Qty.	1 pc(s).

ES EPG/HPG 60 WM 240

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	22 mm	Depth (inches)	0.866 inch
Height	42 mm	Height (inches)	1.654 inch
Width	42 mm	Width (inches)	1.654 inch
Net weight	117 g		

Crimp inserts

Crimp cross-section copper	240	Crimping width	5 mm
Crimping width in mm	5		

Description of contact

Conductor cross-section, max. AWG	450	Conductor cross-section, min. AWG	450
Crimping range, max.	240 mm ²	Type of contact	Euro series cable lug

tool data crimping

Cable lug cross section	nominal	240 mm ²
Crimping type/profile	WM crimp	

Classifications

ETIM 6.0	EC001282	ETIM 7.0	EC001282
ETIM 8.0	EC001282	ETIM 9.0	EC001282
ETIM 10.0	EC001282	ECLASS 9.0	21-04-90-90
ECLASS 9.1	21-01-90-90	ECLASS 10.0	21-04-90-90
ECLASS 11.0	21-04-90-90	ECLASS 12.0	21-04-90-90
ECLASS 13.0	21-04-90-90	ECLASS 14.0	21-04-90-90
ECLASS 15.0	21-04-90-90		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Downloads

Catalogues	Catalogues in PDF-format
------------	--

ES EPG/HPG 60 WM 240

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

240 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	VSTN/-240	Version
Order No.	1497400000	cable lug, terminal end, 240 mm ² , 240 mm ² , None
GTIN (EAN)	4050118306965	
Qty.	25 pc(s).	

240 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KWN-M16/-240 45	Version
Order No.	1495410000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118305203	
Qty.	15 pc(s).	
Type	KWN-M12/-240 45	Version
Order No.	1495400000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118305227	
Qty.	15 pc(s).	
Type	KWN-M20/-240 45	Version
Order No.	1495420000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118305234	
Qty.	15 pc(s).	

ES EPG/HPG 60 WM 240

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Tools

**Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts**

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

Type	EPG 60	Version
Order No.	2453810000	Pressing tools, Tools, Pressing tool, 6mm ² , 300mm ² , Hexagonal crimp,
GTIN (EAN)	4050118468434	WM crimp, Indent crimp, Trapezoidal crimp, Oval crimping
Qty.	1 pc(s).	

240 mm²**The use of insulated connectors guarantees users consistent electrical connection quality in the long term.**

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KRN-M10/-240 S	Version
Order No.	1494340000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118304039	
Qty.	5 pc(s).	
Type	KRN-M16/-240 S	Version
Order No.	1494370000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118304046	
Qty.	5 pc(s).	
Type	KRN-M12/-240 S	Version
Order No.	1494350000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118303933	
Qty.	5 pc(s).	

ES EPG/HPG 60 WM 240

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

240 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KWN-M16/-240 90	Version
Order No.	1494620000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118304237	
Qty.	25 pc(s).	
Type	KWN-M20/-240 90	Version
Order No.	1494630000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118304138	
Qty.	25 pc(s).	
Type	KWN-M10/-240 90	Version
Order No.	1494590000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118304145	
Qty.	25 pc(s).	
Type	KWN-M12/-240 90	Version
Order No.	1494610000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118304244	
Qty.	25 pc(s).	

240 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KP-M16/-240	Version
Order No.	1498420000	cable lug, terminal end, 240 mm ²
GTIN (EAN)	4050118307825	
Qty.	20 pc(s).	

ES EPG/HPG 60 WM 240

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	KP-M12/-240	Version
Order No.	1498410000	cable lug, terminal end, 240 mm ²
GTIN (EAN)	4050118307672	
Qty.	20 pc(s).	
Type	KP-M14/-240	Version
Order No.	1498530000	cable lug, terminal end, 240 mm ²
GTIN (EAN)	4050118307689	
Qty.	20 pc(s).	
Type	KP-M20/-240	Version
Order No.	1498430000	cable lug, terminal end, 240 mm ²
GTIN (EAN)	4050118307832	
Qty.	20 pc(s).	
Type	KP-M10/-240	Version
Order No.	1498390000	cable lug, terminal end, 240 mm ²
GTIN (EAN)	4050118307818	
Qty.	20 pc(s).	

Tools



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 400 mm²
- 360° revolving quick action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- Additional features for APG series:
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB

General ordering data

Type	HPG 60	Version
Order No.	2453820000	6mm ² , 300mm ² , Hexagonal crimp, WM crimp, Indent crimp,
GTIN (EAN)	4050118468427	Trapezoidal crimp, Oval crimping
Qty.	1 pc(s).	

ES EPG/HPG 60 WM 240

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

240 mm²

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KRN-M14/-240	Version
Order No.	1497270000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118306842	
Qty.	25 pc(s).	
Type	KRN-M8/-240	Version
Order No.	1495480000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118304756	
Qty.	25 pc(s).	
Type	KRN-M16/-240	Version
Order No.	1495510000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118304770	
Qty.	25 pc(s).	
Type	KRN-M10/-240	Version
Order No.	1495490000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118305050	
Qty.	25 pc(s).	
Type	KRN-M12/-240	Version
Order No.	1495500000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118305142	
Qty.	25 pc(s).	
Type	KRN-M20/-240	Version
Order No.	1495520000	cable lug, terminal end, 240 mm ² , 240 mm ² - 240 mm ²
GTIN (EAN)	4050118305104	
Qty.	25 pc(s).	