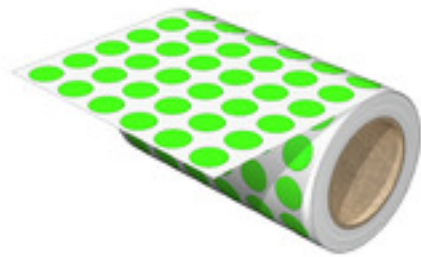


THM VIN DIA 12.5 GN**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Customised identification: EL**

The endless variations of MultiMark markers make them an economical alternative to conventional tag rails or special labels. For any given width, the height can be precisely configured by the software to match the respective markers perfectly. A blade is used to cut the labels individually to the specified size. Perfect for producing large labels for function blocks or complete terminal blocks.

General ordering data

Version	THM, Device markers, green
Order No.	2517950000
Type	THM VIN DIA 12.5 GN
GTIN (EAN)	4050118530162
Qty.	4,200 pc(s).
compatible printer	2599430000 2599440000

THM VIN DIA 12.5 GN

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	0.08 mm	Depth (inches)	0.003 inch
Diameter	12.5 mm	Net weight	0.042 g

Temperatures

Storage temperature	23	Operating temperature range	-30...90 °C
---------------------	----	-----------------------------	-------------

General data

Adhesive	Polyacrylate adhesive	
Approval acc. to UL 969	No	
Colour	green	
Halogen	Yes	
Number of markers per combination	1 Label reel = Device markers	
Number of markers per packaging unit	Form of supply	
Number per roll	1	
Number per sheet	1	
Operating temperature range	-30...90 °C	
Operating temperature range, max.	90 °C	
Operating temperature range, min.	-30 °C	
Printed characters	without	
Printing method	Thermal transfer	
UL 94 flammability rating	HB	
Version	Endless, Self-adhesive	

Device markers

Diameter	12.5 mm	Halogen	Yes
----------	---------	---------	-----

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 9.0	27-40-06-29
ECLASS 9.1	27-40-06-29	ECLASS 10.0	27-40-06-29
ECLASS 11.0	27-28-11-04	ECLASS 12.0	27-28-11-04
ECLASS 13.0	27-28-11-04	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Approvals

ROHS	Conform
------	---------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Downloads

Catalogues	Catalogues in PDF-format
------------	--

THM VIN DIA 12.5 GN**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM 110/360 SW	Version
Order No.	2005070000	Ink ribbon
GTIN (EAN)	4050118390049	
Qty.	1 pc(s).	