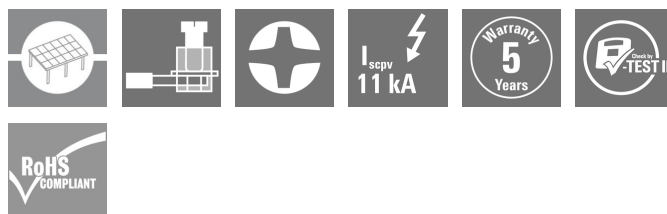


VPU PV II 3 1000**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Product image****General ordering data**

Version	Surge voltage arrester, Low voltage, Surge protection II
Order No.	2530550000
Type	VPU PV II 3 1000
GTIN (EAN)	4050118540550
Qty.	1 pc(s).
Replacement parts	2530660000 2735080000

VPU PV II 3 1000

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	70 mm	Depth (inches)	2.756 inch
Height	96 mm	Height (inches)	3.78 inch
Width	54 mm	Width (inches)	2.126 inch
Mounting dimension - height	75 mm	Net weight	386 g

Temperatures

Storage temperature	85 °C	Operating temperature	-40 °C...85 °C
Humidity	5 - 95% rel. humidity		

Rated data UL

Ambient temperature (operational), max. 85 °C		Rated Voltage U _N	1,100 V
SCCR	50 kA	I _n	20 kA
Category	SPD TYPE 1CA	Ambient temperature (operational), min. -40 °C	
Certificate No. (cURus)	E354261	VPR (DC+/DC-)	2,500 V
VPR (DC-/G)	2,500 V	Voltage type	DC

General data

Number of poles	3	Protection degree	IP20
Colour	black, orange		

Insulation coordination acc. to EN 50178

Pollution severity	2	Surge voltage category	III
--------------------	---	------------------------	-----

Photovoltaic technical data

Discharge current I_n (8/20 μ s)	20 kA	Operating height in the grounded PV system	≤ 2000 m
Operating height in ungrounded PV system	≤ 4000 m	PV system voltage, max. U_{cpv}	1,100 V
Protection level U_p (+/-, -/PE, +/-PE)	≤ 3.8 kV	Requirements class	Type II
Short-circuit current I_{SCP}	11,000 A	Standards	EN 61643-31, EN 50539-11, UL 1449
Total discharge current I_{total} (8/20 μ s)	50 kA		

Rated data IEC / EN

Integrated back-up fuse	No	Leakage current at U_n	30 μ A
Max. continuous voltage, U_c (DC)	1000 V	Number of poles	3
Rated voltage (DC)	1000 V	Response time	≤ 25 ns
SPD type	T2	Signalling contact	No
Standards	EN 61643-31, EN 50539-11, UL 1449	Voltage type	DC

VPU PV II 3 1000

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Connection data

Stripping length	18 mm	Type of connection	Screw connection
Stripping length, rated connection	18 mm	Tightening torque, min.	3 Nm
Tightening torque, max.	4.5 Nm	Clamping range, rated connection	6 mm ²
Clamping range, min.	1.5 mm ²	Clamping range, max.	35 mm ²
Wire cross-section, solid, min.	1.5 mm ²	Wire cross-section, solid, max.	16 mm ²
Wire connection cross section, finely stranded, min.	1.5 mm ²	Wire connection cross section, finely stranded, max.	25 mm ²
Connection cross-section, stranded, min.	1.5 mm ²	Connection cross-section, stranded, max.	35 mm ²

Electrical data

Voltage type	DC
--------------	----

Guarantee

Time interval	5 years
---------------	---------

Classifications

ETIM 6.0	EC000941	ETIM 7.0	EC000941
ETIM 8.0	EC000941	ETIM 9.0	EC000941
ETIM 10.0	EC000941	ECLASS 9.0	27-13-08-05
ECLASS 9.1	27-13-08-05	ECLASS 10.0	27-13-08-05
ECLASS 11.0	27-13-08-05	ECLASS 12.0	27-17-90-90
ECLASS 13.0	27-17-90-90	ECLASS 14.0	27-17-90-90
ECLASS 15.0	27-17-90-90		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Approvals

Approvals



Approvals MAMID	https://mdcop.weidmueller.com/mediadelivery/rendition/900_319222/-T1z1mm-S800/ https://mdcop.weidmueller.com/mediadelivery/rendition/900_319230/-T1z1mm-S800/ https://mdcop.weidmueller.com/mediadelivery/rendition/900_319263/-T1z1mm-S800/
-----------------	---

ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E354261

VPU PV II 3 1000

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Approval/Certificate/Document of Con-
formity

[CE_VPU_PV](#)

Engineering Data

[CAD data – STEP](#)

Tender specification

[Ausschreibungstext DE](#)

[Tenderspecification EN](#)

User Documentation

[Beipackzettel / Instruction sheet](#)

[Fuse values in DC application](#)

[FL_Applikationsnotiz_SPDs in DC Anwendungen_DE_WEB](#)

[Sicherungswerte in DC Anwendungen](#)

Catalogues

[Catalogues in PDF-format](#)


VPU PV II 3 1000

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Electric symbol

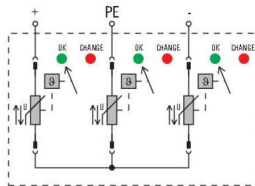

Circuit diagram

VPU PV II 3 1000

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Replacement parts**VPU Series**

Extensive accessories round off the product range

General ordering data

Type	VPU LOCKING CLIP S
Order No.	2735080000
GTIN (EAN)	4050118826050
Qty.	10 pc(s).

Spare Arrester**General ordering data**

Type	VPU PV II O 1000	Version
Order No.	2530660000	Surge voltage arrester, Low voltage, Accessories, Spare arrester
GTIN (EAN)	4050118540871	
Qty.	9 pc(s).	

VPU PV II 3 1000**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****VPU Series**

Extensive accessories round off the product range

General ordering data

Type	VPU PV EXTENDER
Order No.	3123510000
GTIN (EAN)	4099987270199
Qty.	9 pc(s).

Slotted screwdriver

VDE insulated slot-head screwdriver, SDI DIN 7437, ISO 2380/2, drive output acc. to DIN 5264, ISO 2380/1.
SoftFinish grip

General ordering data

Type	SDIS 1.0X5.5X125	Version
Order No.	2749850000	Screwdriver, Blade width (B): 5.5 mm, Blade length: 125 mm, Blade
GTIN (EAN)	4050118897050	thickness (A): 1 mm
Qty.	1 pc(s).	

VPU PV II 3 1000

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	ESG 6/15 K MC NE WS	Version
Order No.	1880100000	ESG, Device markers x 15 mm, PA 66, Colour: white, Self-adhesive
GTIN (EAN)	4032248478781	
Qty.	200 pc(s).	

Crosshead screwdriver Phillips



VDE insulated crosshead screwdriver, for Phillips screws, SDIK PH DIN 7438, ISO 8764/2-PH, output to ISO 8764-PH, SoftFinish grip

General ordering data

Type	SDIK PH1 X 80	Version
Order No.	2749890000	Screwdriver, Blade width (B): 1 mm, 80 mm, Blade thickness (A): 1
GTIN (EAN)	4050118897098	
Qty.	1 pc(s).	