 


FF 22 55/230V BK**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration**

The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

General ordering data

Version	Filter fan, IP55, black
Order No.	2556650000
Type	FF 22 55/230V BK
GTIN (EAN)	4050118567274
Qty.	1 pc(s).
Delivery status	This article will no longer be available in the future.
Available until	2025-12-31

FF 22 55/230V BK

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	75 mm	Depth (inches)	2.953 inch
Height	145 mm	Height (inches)	5.709 inch
Width	145 mm	Width (inches)	5.709 inch
Net weight	700 g		

Temperatures

Operating temperature range	-40...55 °C
-----------------------------	-------------

General data

Colour	black		
Current consumption	Mains frequency	50 Hz	
	Current	0.12 A	
	Mains frequency	60 Hz	
	Current	0.18 A	
EMC version	No		
Fan type	Roof fan		
Filter class	G 4		
Fuse	6 A		
Height of installation cut-outs	125 mm		
MTBF	37,500 h		
Mounting depth	70 mm		
Mounting height	5 mm		
Noise emission	44 dB(A)		
Operating temperature range	-40...55 °C		
Power	Mains frequency	50 Hz	
	nominal	19 W	
	Mains frequency	60 Hz	
	nominal	18 W	
Protection class (UL)	Type 12		
Rated AC voltage	230 V		
Rated voltage	230 V AC $\pm$ 10%		
Size	2		
Type of connection	Terminal strip		
Type of mounting	Snap-on		
UL 94 flammability rating	V-0		
UV-resistant	Yes		
Volume flow with exhaust filter	Mains frequency	50 Hz	
	Volume flow	40 m ³ /h	
	Exhaust filter	IP55	
	Mains frequency	60 Hz	
	Volume flow	46 m ³ /h	
	Exhaust filter	IP55	
Volume flow, free-blowing	Mains frequency	50 Hz	
	Volume flow	56 m ³ /h	
	Mains frequency	60 Hz	
	Volume flow	64 m ³ /h	
Volume flow, free-blowing at 50 Hz	56 m ³ /h		
Volume flow, free-blowing at 60 Hz	64 m ³ /h		
Width of installation cut-outs	125 mm		
With filter	Yes		
With protective cover	Yes		

FF 22 55/230V BK

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Classifications

ETIM 6.0	EC000320	ETIM 7.0	EC000320
ETIM 8.0	EC000320	ETIM 9.0	EC000320
ETIM 10.0	EC000320	ECLASS 9.1	27-18-07-16
ECLASS 10.0	27-18-07-16	ECLASS 11.0	27-18-07-16
ECLASS 12.0	27-18-07-16	ECLASS 13.0	27-18-07-16
ECLASS 14.0	27-18-07-16	ECLASS 15.0	27-18-07-16

Approvals

Approvals



Approvals MAMID https://mdcop.weidmueller.com/mediadelivery/rendition/900_319222/-T1z1mm-S800/ https://mdcop.weidmueller.com/mediadelivery/rendition/900_319230/-T1z1mm-S800/

ROHS Conform
 UL File Number Search UL Website
 Certificate No. (cURus) E252704

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

Downloads

Approval/Certificate/Document of Conformity [EU Declaration of Conformity](#)
 Engineering Data [CAD data – STEP](#)
 User Documentation [Installation- and operating instructions](#)
 Catalogues [Catalogues in PDF-format](#)


FF 22 55/230V BK

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany


www.weidmueller.com

Drawings

Graph

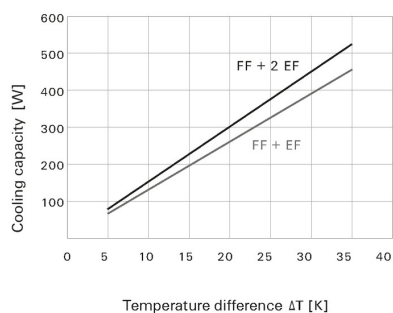

Graph

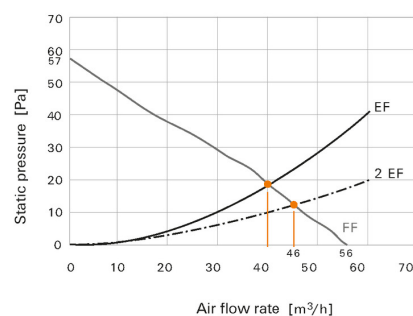

FF 22 55/230V BK

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Filter fan



The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

General ordering data

Type	FF-FIMT 2X 55	Version
Order No.	2556670000	Filter mat, IP55, white
GTIN (EAN)	4050118567298	
Qty.	5 pc(s).	
Type	FF-FIMT 2X 54	Version
Order No.	2556660000	Filter mat, IP54, white
GTIN (EAN)	4050118567281	
Qty.	5 pc(s).	

Exhaust filter



The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats. Thought out details as the functional flap cover enable a fast and tool-less change of the filter mats which saves time and money.

General ordering data

Type	EF 20 55 GY	Version
Order No.	2557110000	Exhaust filter, IP55, grey
GTIN (EAN)	4050118567748	
Qty.	1 pc(s).	
Type	EF 20 54 BK	Version
Order No.	2557100000	Exhaust filter, IP54, black
GTIN (EAN)	4050118567731	
Qty.	1 pc(s).	
Type	EF 20 54 GY	Version
Order No.	2557090000	Exhaust filter, IP54, grey
GTIN (EAN)	4050118567724	
Qty.	1 pc(s).	
Type	EF 20 55 BK	Version
Order No.	2557120000	Exhaust filter, IP55, black
GTIN (EAN)	4050118567755	
Qty.	1 pc(s).	