

FF-EMC 43 54/230V BK**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

For use near electromagnetic fields. Secure contact surface without the need for a beryllium copper seal and particularly environmentally friendly as no metal reinforced plastics are required.

General ordering data

Version	Filter fan, IP54, black
Order No.	2557400000
Type	FF-EMC 43 54/230V BK
GTIN (EAN)	4050118568035
Qty.	1 pc(s).
Delivery status	Discontinued
Available until	2023-11-10

FF-EMC 43 54/230V BK

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	119 mm	Depth (inches)	4.685 inch
Height	252 mm	Height (inches)	9.921 inch
Width	252 mm	Width (inches)	9.921 inch
Net weight	1,594 g		

Temperatures

Operating temperature range	-40...55 °C
-----------------------------	-------------

General data

Colour	black		
Current consumption	Mains frequency	50 Hz	
	Current	0.32 A	
	Mains frequency	60 Hz	
	Current	0.26 A	
EMC version	EN 61000-3-2,-3, EN 61000-6-2, 3		
Fan type	Shelf		
Filter class	G 4		
Fuse	6 A		
Height of installation cut-outs	224 mm		
MTBF	40,000 h		
Mounting depth	113 mm		
Mounting height	6 mm		
Noise emission	42 dB(A)		
Operating temperature range	-40...55 °C		
Power	Mains frequency	50 Hz	
	nominal	45 W	
	Mains frequency	60 Hz	
	nominal	39 W	
Protection class (UL)	Type 12		
Rated AC voltage	230 V		
Rated voltage	230 V AC $\pm$ 10%		
Size	4		
Type of connection	Spring contact		
Type of mounting	Snap-on		
UL 94 flammability rating	V-0		
Volume flow with exhaust filter	Mains frequency	50 Hz	
	Volume flow	231 m ³ /h	
	Exhaust filter	IP54	
	Mains frequency	60 Hz	
	Volume flow	265 m ³ /h	
	Exhaust filter	IP54	
Volume flow, free-blowing	Mains frequency	50 Hz	
	Volume flow	256 m ³ /h	
	Mains frequency	60 Hz	
	Volume flow	292 m ³ /h	
Volume flow, free-blowing at 50 Hz	256 m ³ /h		
Volume flow, free-blowing at 60 Hz	292 m ³ /h		
Width of installation cut-outs	224 mm		
With filter	Yes		

FF-EMC 43 54/230V BK**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Classifications**

ETIM 6.0	EC000320	ETIM 7.0	EC000320
ETIM 8.0	EC000320	ETIM 9.0	EC000320
ETIM 10.0	EC000320	ECLASS 9.1	27-18-07-16
ECLASS 10.0	27-18-07-16	ECLASS 11.0	27-18-07-16
ECLASS 12.0	27-18-07-16	ECLASS 13.0	27-18-07-16
ECLASS 14.0	27-18-07-16	ECLASS 15.0	27-18-07-16

Approvals

ROHS	Conform
------	---------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Downloads

Approval/Certificate/Document of Conformity	EU Declaration of Conformity
Engineering Data	CAD data – STEP
User Documentation	Installation- and operating instructions
Catalogues	Catalogues in PDF-format

FF-EMC 43 54/230V BK


Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com


Drawings

Graph


Shielding effectiveness measurements

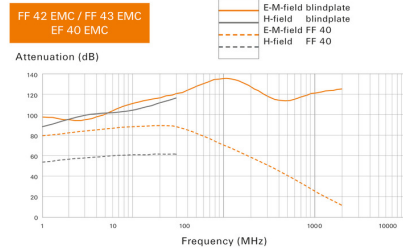

Graph

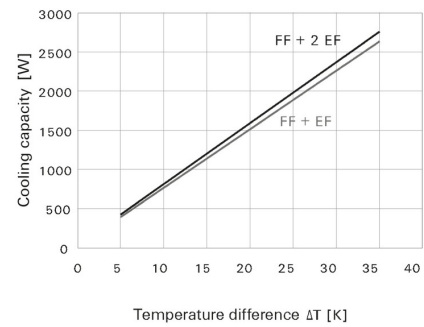

Graph

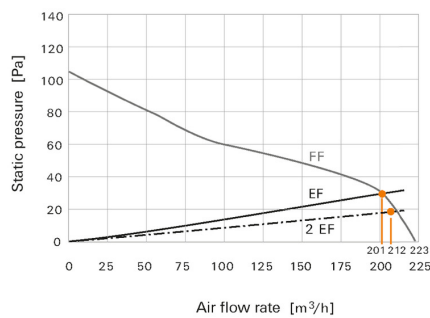

FF-EMC 43 54/230V BK

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Exhaust filter



The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats. Thought out details as the functional flap cover enable a fast and tool-less change of the filter mats which saves time and money.

General ordering data

Type	EF-EMC 40 54 BK	Version
Order No.	2557660000	Exhaust filter, IP54, black
GTIN (EAN)	4050118568301	
Qty.	1 pc(s).	
Type	EF-EMC 40 55 BK	Version
Order No.	2557680000	Exhaust filter, IP55, black
GTIN (EAN)	4050118568325	
Qty.	1 pc(s).	
Type	EF-EMC 40 54 GY	Version
Order No.	2557650000	Exhaust filter, IP54, grey
GTIN (EAN)	4050118568295	
Qty.	1 pc(s).	
Type	EF-EMC 40 55 GY	Version
Order No.	2557670000	Exhaust filter, IP55, grey
GTIN (EAN)	4050118568318	
Qty.	1 pc(s).	

Filter fan



The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

General ordering data

Type	FF-FIMT 4X 54	Version
Order No.	2556790000	Filter mat, IP54, white
GTIN (EAN)	4050118567410	
Qty.	5 pc(s).	
Type	FF-FIMT 4X 55	Version
Order No.	2556800000	Filter mat, IP55, white
GTIN (EAN)	4050118567427	
Qty.	5 pc(s).	