

ESG-FO 8/20 MM GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Guaranteed long service life: ESG**

The multi-colour and multi-format labels have a strong adhesive layer to ensure the best possible adhesion to the underlying surface. Double laminated polyester makes the basic material very thin and yet extremely tear-resistant.

Your benefits with MultiMark

- “Different materials for various requirements”
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

General ordering data

Version	ESG, Device markers, 8 x 20 mm, yellow
Order No.	2620960000
Type	ESG-FO 8/20 MM GE
GTIN (EAN)	4050118626025
Qty.	1,000 pc(s).
compatible printer	2599430000 2599440000

ESG-FO 8/20 MM GE

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	0.55 mm	Depth (inches)	0.022 inch
Height	8 mm	Height (inches)	0.315 inch
Width	20 mm	Width (inches)	0.787 inch
Net weight	0.05 g		

Temperatures

Operating temperature range	-30...80 °C
-----------------------------	-------------

General data

Adhesive	PE-foam with acrylic adhesive	Approval acc. to UL 969	Yes
Colour	yellow	Halogen	No
Material	Polyester	Number per roll	1,000
Operating temperature range	-30...80 °C	Operating temperature range, max.	80 °C
Operating temperature range, min.	-30 °C	Printed characters	without
Size of labelling field	8 x 20 mm	UL 94 flammability rating	V-0
Version	Self-adhesive, halogen-free	Width	20 mm

Device markers

Halogen	No
---------	----

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 9.0	27-40-06-29
ECLASS 9.1	27-40-06-29	ECLASS 10.0	27-40-06-29
ECLASS 11.0	27-28-11-04	ECLASS 12.0	27-28-11-04
ECLASS 13.0	27-28-11-04	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Approvals

ROHS	Conform
------	---------

Downloads

Catalogues	Catalogues in PDF-format
------------	--

ESG-FO 8/20 MM GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

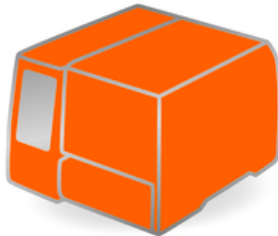


ESG-FO 8/20 MM GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

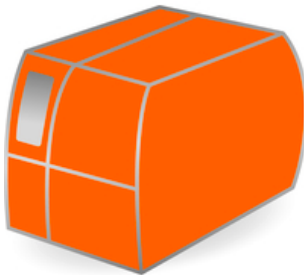
Germany

www.weidmueller.com**Accessories****THM MULTIMARK**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MULTIMARK ROLLER 115
Order No.	1357420000
GTIN (EAN)	4050118160314
Qty.	1 pc(s).

THM MULTIMARK PLUS

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MULTIMARK PLUS ROLLER 1 ...
Order No.	2672590000
GTIN (EAN)	4050118708097
Qty.	1 pc(s).

ESG-FO 8/20 MM GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM 76/360 SW	Version
Order No.	2005080000	Ink ribbon
GTIN (EAN)	4050118389951	
Qty.	1 pc(s).	