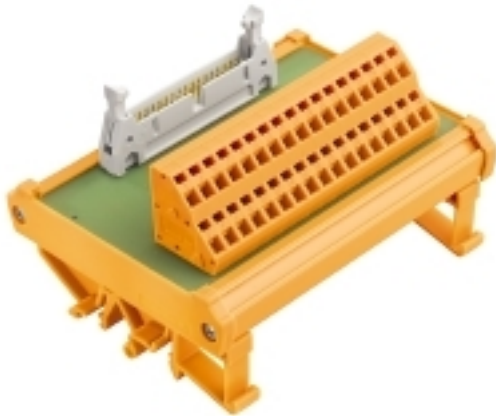


RS F20 Z**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

Passive interfaces for signal transmission on a flat-cable connector equipped with a tension-clamp connection in accordance with IEC 603-1 / DIN 41651. The main features include:

- Group with 10- to 64-pole connectors
- One-to-one electrical connection between controller and field connections.
- Very compact modules can be attached to conventional TS35 or TS32 mounting rails.
- Longer attachment hooks

General ordering data

Version	Interface, RSF, Plug-in connector in acc. with IEC60603-13 / DIN41651, 20-pole, Tension-clamp connection
Order No.	8537110000
Type	RS F20 Z
GTIN (EAN)	4032248172771
Qty.	1 pc(s).

RS F20 Z

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	64 mm	Depth (inches)	2.52 inch
Height	87 mm	Height (inches)	3.425 inch
Width	65 mm	Width (inches)	2.559 inch
Net weight	121 g		

Temperatures

Storage temperature	-40...70 °C	Operating temperature	0...55 °C
---------------------	-------------	-----------------------	-----------

Rated data UL

Operating temperature UL, max.	25 °C	Operating temperature UL, min.	0 °C
Rated current I_N	1 A	Rated voltage U_N	≤ 60 V AC / 75 V DC

Connection Data

Connection (field side)	LM2NZF 5.08mm	Connection on control side	Plug-in connector in acc. with IEC60603-13 / DIN41651
Earthing	No	Number of poles (control side)	20-pole

Rating data

Rated voltage	60 V AC / 75 V DC	Rated current per connection	1 A
---------------	-------------------	------------------------------	-----

Insulation coordination (EN50178)

According to	DIN EN 50178	Rated insulation voltage	100 V
Surge voltage category	II	Pollution severity level	2
Pulse voltage test (1,2/50µs)	0.8 kV		

Connection field

Clamping range, max.	2.5 mm ²	Clamping range, min.	0.13 mm ²
Flexible with sleeve, max.	1.5 mm ²	Flexible with sleeve, min.	0.25 mm ²
Flexible, max. H05(07) V-K	1.5 mm ²	Flexible, min. H05(07) V-K	0.2 mm ²
Max. wire cross-section, AWG	AWG 14	Min. wire cross-section, AWG	AWG 24
Sleeve with plastic collar, max.	1.5 mm ²	Solid, max. H05(07) V-U	2.5 mm ²
Solid, min. H05(07) V-U	0.2 mm ²	Stripping length	7.5 mm
Type of connection	Tension-clamp connection		

Classifications

ETIM 6.0	EC002780	ETIM 7.0	EC002780
ETIM 8.0	EC002780	ETIM 9.0	EC002780
ETIM 10.0	EC002780	ECLASS 9.0	27-14-11-52
ECLASS 9.1	27-14-11-52	ECLASS 10.0	27-14-11-52
ECLASS 11.0	27-14-11-52	ECLASS 12.0	27-14-11-52
ECLASS 13.0	27-14-11-52	ECLASS 14.0	27-14-11-52
ECLASS 15.0	27-14-11-52		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Creation date June 13, 2025 8:49:04 PM CEST

RS F20 Z**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Approvals**

Approvals



Approvals MAMID	https://mdcop.weidmueller.com/mediadelivery/rendition/900_319222/-T1z1mm-S800/ https://mdcop.weidmueller.com/mediadelivery/rendition/900_319262/-T1z1mm-S800/
-----------------	---

ROHS	Conform
------	---------

UL File Number Search	UL Website
-----------------------	------------

Certificate No. (UR)	E141197
----------------------	---------

Downloads

Approval/Certificate/Document of Conformity	Declaration of Conformity
---	---

Engineering Data	CAD data – STEP
------------------	---------------------------------


Catalogues	Catalogues in PDF-format
------------	--

RS F20 Z

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

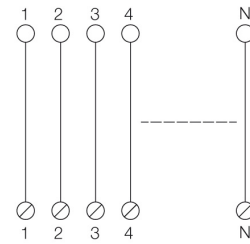

N: Number of poles