


Ground Rod Clamps

A dependable ground connection offered at a substantial savings.

Type G — Budget-Line Ground Clamps

- Cast of high-strength corrosion-resistant copper alloy
- Furnished with hex head bolts
- Simplified, compact design makes lasting, trouble-free connection
- UL® Listed for direct burial

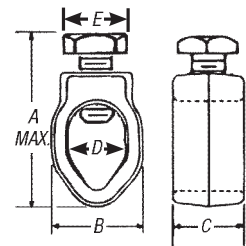

CAT. NO.	NOMINAL ROD DIA.		WIRE RANGE				DIMENSIONS (IN.)					
	(IN.)	(MM)	MAX.	MIN.	MAX. (MM²)	MIN. (MM²)	A (MAX.) BOLT	SCREW THREAD SIZE UNC-2A	B	C	D	E
G3*	¾	9.5	4 Str.	10 Sol.	21.1	5.2	1⅝	⅝-18	1⅞	½	27⁄64	¾
G4	½	12.7	2 Str.	10 Sol.	33.6	5.2	—	¾-16	27⁄32	¾	37⁄64	½
G5‡	¾	15.8	2 Str.	10 Sol.	33.6	5.2	—	¾-16	29⁄32	¾	43⁄64	½
G6	¾	19.0	2 Str.	10 Sol.	33.6	5.2	—	¾-16	1⅞	¾	13⁄16	½

* Not UL Listed.



‡ RUS Accepted.

Add suffix P to Cat. No. for tin-plated clamp.

Axial groove keeps wire and rod in perfect alignment.

Types GG and GGH — Heavy-Duty Ground Rod Clamps

- Cast of high-strength corrosion-resistant copper alloy
- Both hex head bolts and socket set screws available
- Floating pressure bar distributes pressure evenly over large area of ground wire

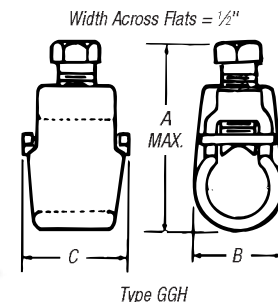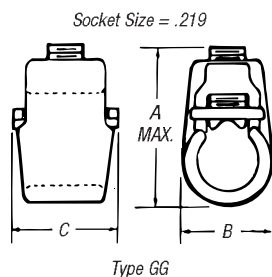

CAT. NO.*		NOMINAL ROD DIA.		WIRE RANGE				DIMENSIONS (IN.)				
SOCKET SET SCREW	HEX HEAD BOLT	(IN.)	(MM)	MAX.	MIN.	MAX. (MM²)	MIN. (MM²)	A (MAX.) SOCKET SCREW	A (MAX.) HEX BOLT	SCREW THREAD SIZE UNC-2A	B	C
GG12	GG12H	1/2	12.7	2 Str.	8 Sol.	33.6	8.3	1 13/64	1 13/16	1/4-14	27/32	1 1/16
GG58	GG58H	3/4	15.8	2 Str.	8 Sol.	53.6	8.3	1 5/64	2 1/32	1/4-14	61/64	1 1/16
—	GG34H	3/4	19.0	4/0 Str.	8 Sol.	120.6	8.3	—	3	1/2-14	1 3/8	1 1/4

* Add suffix P to Cat. No. for tin-plated clamp.

GG34H has no pressure bar or axial groove.