


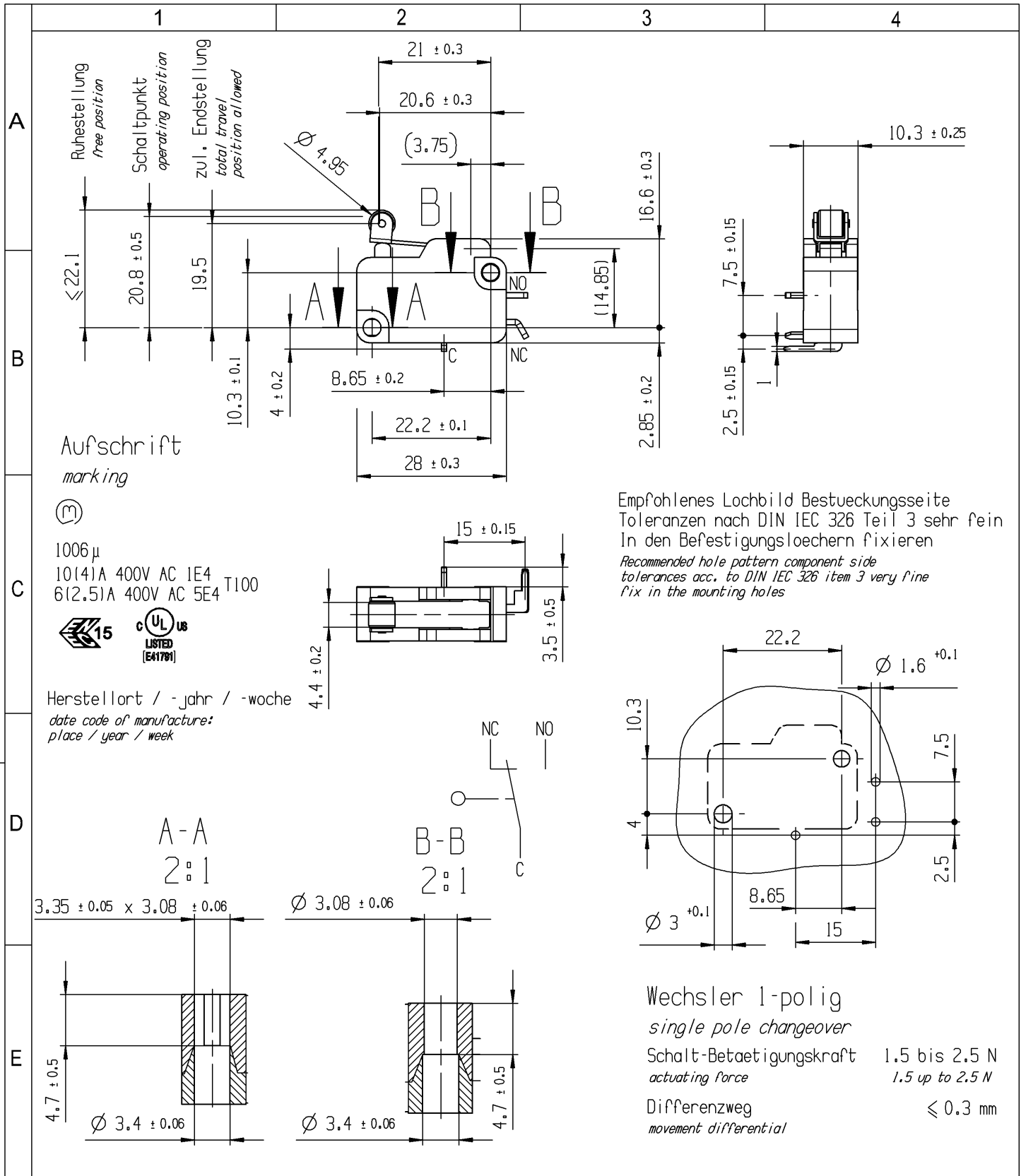

Empfohlenes Lochbild Bestueckungsseite
Toleranzen nach DIN IEC 326 Teil 3 sehr fein
In den Befestigungsloechern fixieren
Recommended hole pattern component side
tolerances acc. to DIN IEC 326 item 3 very fine
fix in the mounting holes

Wechsler 1-polig
single pole changeover
Schalt-Betaetigungskraft 1.5 bis 2.5 N
actuating force 1.5 up to 2.5 N
Differenzweg ≤ 0.3 mm
movement differential

-	-	-	1006.4103-XX
Figure	Type	Customer No.	Art.No.-PI
General tolerances			
All dimensions are in millimetres	Shape and location ◎ ≡	Angle ± 2 °	Edge tolerance
			Length 0-6 ± 0.1 >6-15 ± 0.15 >15-30 ± 0.2 >30-70 ± 0.3 >70-120 ± 0.4 >120 ± 0.8
			Radii ± 0.2 ± 0.3 ± 0.5 ± 10%
e	134431	2020-10-22	HHE
d	128297	2020-01-29	HHE
c	104406	2016-09-06	LM
b	100166	2016-05-13	DRI
Index	MEC-No.	Date (YYYY-MM-DD)	Edited by
Sheet 01		Ident. K	Document number 10064103
Format DIN A4		Projection	Scale 1:1
System NX V11.0		Snap action switch	
Replacement of Zg.gl.Nr.v.10.03.2004		MARQUARDT	