

 



A

B


C

D

E

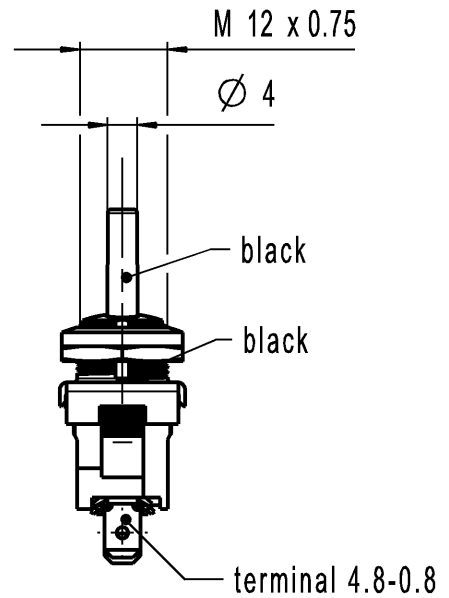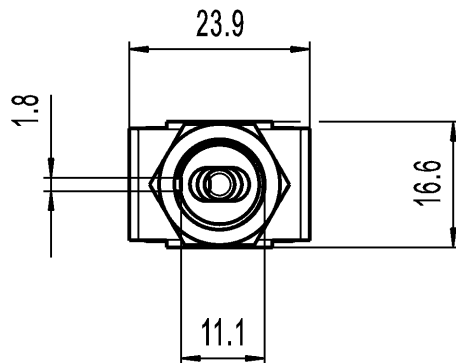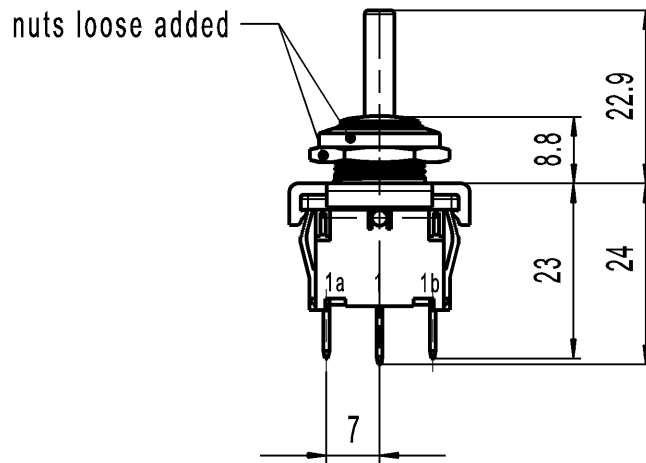

SPDT
With centre-off
Biased from both sides
Suitable for appliances of class II

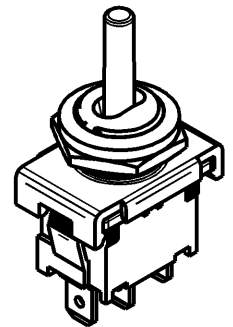

Marking

1828. μ
6(2)/250~ T100/55



Code of manufacture: place/year/week

-		-				-		1828.1301-XX			
Figure		Type				Customer No.		Art.No.-PI			
General tolerances						Sheet 01			Ident. K	Document number 18281301	Index d
All dimensions are in millimetres		Shape and location 	Angle $\pm 2^\circ$	Edge tolerance 							
					0-6	± 0.2	$\pm$				
					>6-15	± 0.4	$\pm$				
					>15-30	± 0.4	$\pm$				
					>30-70	$\pm$	$\pm$				
					>70-120	$\pm$					
					>120	$\pm$					
d	131663	2020-08-26		THAKARES		Format DIN A4	Projection 	Scale 1:1	Appliance Switch		
c	64505	2010-01-27		MUT							
b	56042	2008-01-16		VOR							
a	29873	2000-06-19		BMI		System NX V11.0			 MARQUARDT		
Index	MEC-No.	Date (YYYY-MM-DD)		Edited by		Replacement of Zg.gl.Nr.v.15.09.2000					