




Heyco® Plugs for Square Tubing

PSTR Series - Ribbed Fit

TUBE DIMENSIONS					PART NO.	DESCRIPTION	PART DIMENSIONS				
Inside Dimension Range				Typical Gauge			Black	A		B	
Minimum	Maximum							Outside Dimension		Depth	
in.	mm.	in.	mm.				in.	mm.	in.	mm.	
.37	9,4	.40	10,2	16 - 18	G5280	PST R-50-16	.50	12,7	.44	11,2	
.46	11,8	.56	14,2	14 - 20	G5281	PST R-63-14	.63	15,9	.43	10,9	
.48	12,2	.58	14,8	10 - 14	G5282	PST R-75-10	.75	19,1			
.58	14,8	.68	17,3	14 - 20	G5283	PST R-75-14					
.71	18,1	.81	20,6	14 - 20	G5284	PST R-88-14	.88	22,2			
.73	18,6	.83	21,2	10 - 14	G5285	PST R-100-10	1.00	25,4			
.83	21,2	.93	23,6	14 - 20	G5287	PST R-100-14					
.96	24,5	1.06	26,9	14 - 20	G5289	PST R-113-14	1.13	28,6	.49	12,4	
.98	24,9	1.08	27,5	10 - 14	G5290	PST R-120-10	1.25	31,8	.52	13,2	
1.08	27,5	1.18	30,0	14 - 20	G5291	PST R-120-14					
1.11	28,2	1.21	30,8	10 - 14	G5292	PST R-138-10	1.38	34,9			
1.21	30,8	1.31	33,3	14 - 20	G5293	PST R-138-14					
1.23	31,3	1.33	33,9	10 - 14	G5294	PST R-150-10	1.50	38,1			
1.33	33,9	1.43	36,3	14 - 20	G5295	PST R-150-14					
1.48	37,6	1.58	40,2	10 - 14	G5296	PST R-170-10	1.75	44,5			
1.58	40,2	1.68	42,7	14 - 20	G5297	PST R-170-14					
1.52	38,7	1.67	42,4	4 - 8	G5298	PST R-200-04	2.00	50,8			
1.73	44,0	1.83	46,6	10 - 14	G5299	PST R-200-10					
1.83	46,6	1.93	49,0	14 - 20	G5300	PST R-200-14					
1.98	50,3	2.08	52,9	10 - 14	G5301	PST R-225-10	2.25	57,2			
2.09	53,2	2.23	56,7	6 - 10	G5302	PST R-250-06	2.50	63,5	.56	14,2	
2.23	56,7	2.33	59,3	10 - 14	G5303	PST R-250-10	2.50	63,5	.50	12,7	
2.37	60,2	2.45	62,2	16 - 23	G5304	PST R-250-16	2.50	63,5	.56	14,2	

Standard color black.

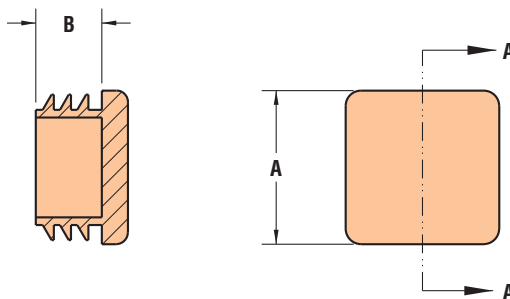

Material LDPE - Low Density Polyethylene
Maximum Temperature Rating 175°F (79°C)

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[G5301](#) [G5291](#) [G5294](#) [G5299](#) [G5293](#) [G5281](#) [G5304](#) [G5283](#) [G5295](#) [G5280](#) [G5297](#) [G5298](#) [G5284](#) [G5302](#)
[G5285](#) [G5290](#) [G5300](#) [G5282](#) [G5287](#) [G5289](#) [G5303](#) [G5296](#) [G5292](#)