

COMMON MODE CHOKES FOR ADSL AND VDSL




- RoHS peak reflow solder temperature rating 245°C
- RoHS peak wave solder temperature rating 260°C
- For use in XDSL interfaces
- Effective reduction of C. M. noise caused by AM broadcast or ham radio
- Isolation 1500V line to line

Electrical Specifications @ 25°C — Operating Temperature -40°C to 85°C


RoHS Compliant Part No.	C. M. Attenuation (dB TYP)			Isolation Voltage (Vrms)	Mounting
	@ 500kHz	@ 1MHz	@ 10MHz		
B4001NL	45	49	35	1500	THT
B4003NL	45	49	35	1500	SMT
BX4053NL	45	49	35	1500	SMT

NOTE: Surge Voltage Capability — Metallic: 800Vpeak 10/560µsec. Long.: 2400Vpeak 10/700µsec. **BX4053NL** is a dual choke. Please add the suffix "T" for Tape & Reel orders (i.e. B4003NL becomes B4003NLT).

Mechanicals

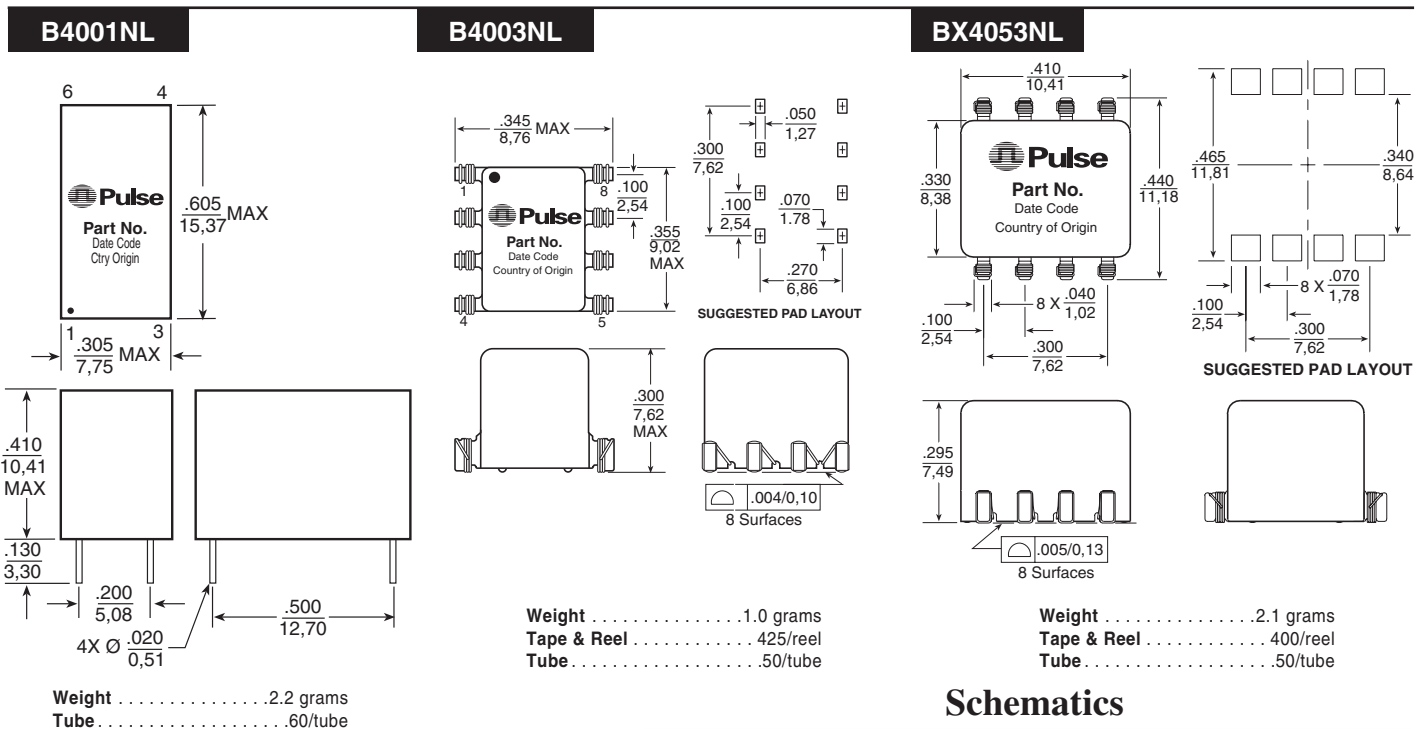

Schematics

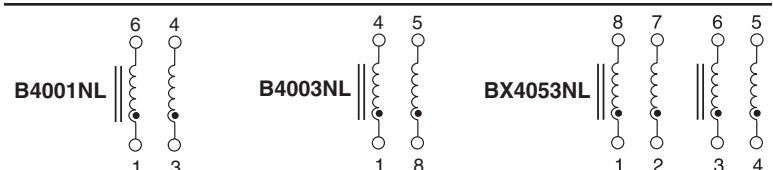

For More Information:

Pulse Worldwide Headquarters
Two Pearl Buck Court
Bristol, PA 19007
U.S.A.

Pulse Europe
Einsteinstrasse 1
D-71083 Herrenberg
Germany

Pulse China Headquarters
B402, Shenzhen Academy of
Aerospace Technology Bldg.
10th Kejinan Rd.
High-Tech Zone
Nanshan District
Shenzhen, PR China 518057
Tel: 86 755 33966678
Fax: 86 755 33966700

Pulse North China
Room 2704/2705
Super Ocean Finance Ctr.
2067 Yan An Rd. West
Shanghai 200336
China
Tel: 86 21 62787060
Fax: 86 2162786973

Pulse South Asia
135 Joo Seng Rd.
#03-02
PM Industrial Bldg.
Singapore 368363
Tel: 65 6287 8998
Fax: 65 6280 0080

Pulse North Asia
No. 26, Kao Ching Rd.
Yang Mei Chen
Taoyuan Hsien
Taiwan
R. O. C.
Tel: 886 3 4643715
Fax: 886 3 4641911

www.pulseeng.com

Tel: 215 781 6400

Fax: 215 781 6403

Tel: 49 7032 7806 0

Fax: 49 7032 7806 135

Performance warranty of products offered on this data sheet is limited to the parameters specified. Data is subject to change without notice. Other brand and product names mentioned herein may be trademarks or registered trademarks of their respective owners. © Copyright, 2009. Pulse Engineering, Inc. All rights reserved.

www.pulseeng.com

B912.F (10/09)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pulse:

[BX4053](#)