


MULTILAYER DIRECTIONAL COUPLER SPECIFICATION

P/N: **HHM2942A2**

[MECHANICAL DIMENSIONS]

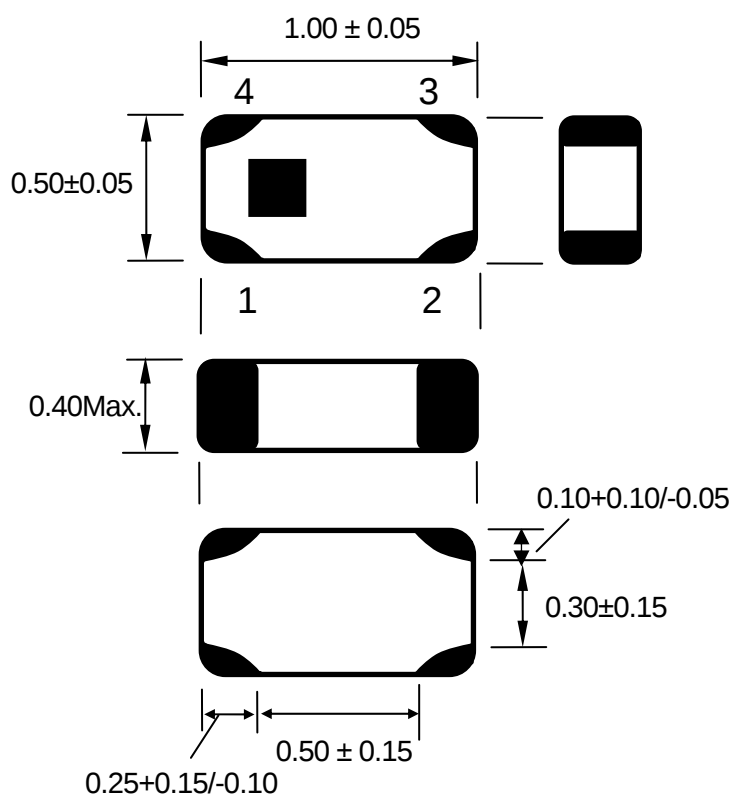

Pin configuration

1. Coupling
2. 50 ohm term
3. Output
4. Input

Unit: mm

ELECTRICAL CHARACTERISTICS

Frequency	Coupling	Ins.Loss(1)	Ins.Loss(2)	Directivity	VSWR
2400-2500	18.2+/-1.0	0.25	0.28	15	1.3 Max.
4900-5850	11.7+/-1.5	0.45	0.50	15	1.3 Max.
MHz	dB	dB	dB	dB	

Ins. Loss(1):at 25 degree

Ins.Loss(2):at Operating Temperature

TEMPERATURE RANGE

Storage Temperature : -40 ~ +85 °C


Operating Temperature : -40 ~ +85 °C

[FREQUENCY CHARACTERISTICS]


HHM2942A1

Smample data


Coupling

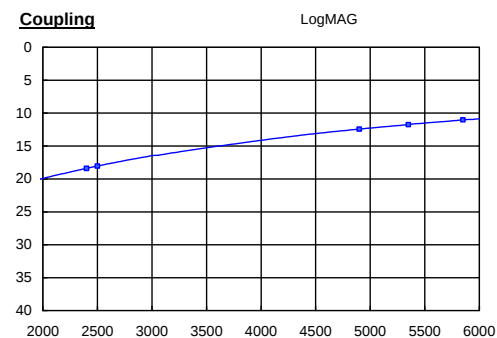


Isolation&Directivity

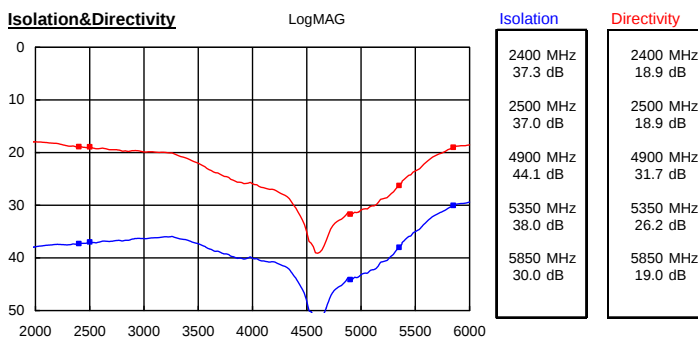


Insertion Loss

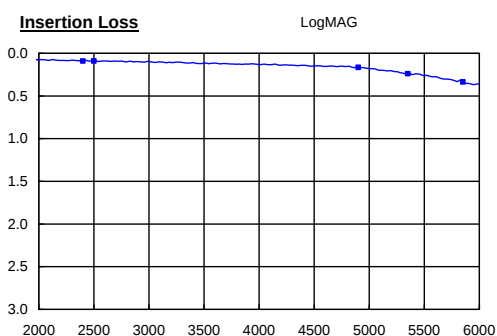

VSWR

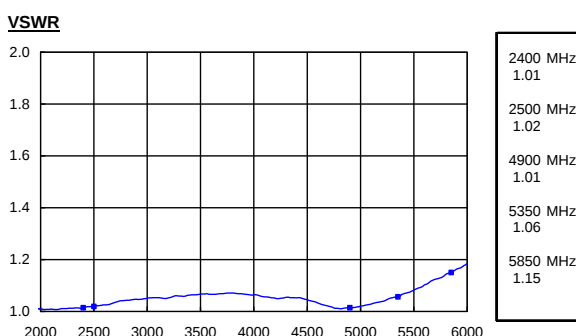

[RECOMMENDED LANDPATTERN]

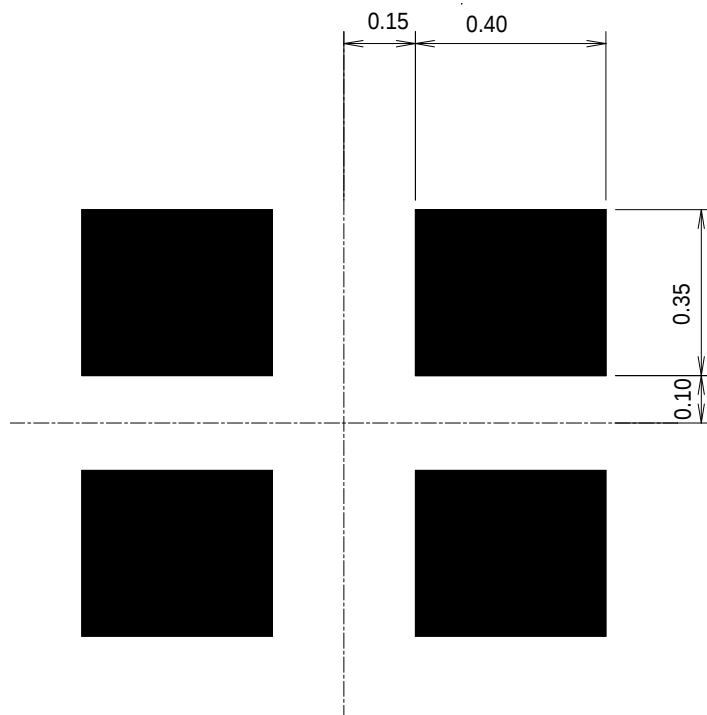

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

TDK:

[HHM2942A2](#)