



## LUMAWISE ENDURANCE N ANSI C136.10 RECEPTACLE ASSEMBLY

TE Connectivity (TE)'s LUMAWISE Endurance N Receptacle Assembly is ideal for outdoor commercial and utility lighting the ANSI C136.10 compliant receptacle offers three robust twist lock contacts to provide a reliable power connection to lighting control modules. In applications where rotation is desired in order to point a photo node due north the Rotatable Receptacle Assembly offering allows rotation up to 355 degrees. ANSI C136.10 compliant receptacles provide an electrical and mechanical connection between an ANSI C136.10 compliant control and luminaire. TE's LUMAWISE Endurance N receptacles provide IP66 protection in harsh outdoor environments when mated with Endurance N control bases and caps.

### BENEFITS

- Robust twist lock contacts for a reliable power interconnect
- Receptacle comes pre-terminated with wire leads for ease of integration into new or existing light fixtures
- Available with 105° and 150°C rated wire insulation for varying temperature rated luminaires
- Rotatable receptacle offering fully rotates up to 355 degrees
- Provides IP66 rating to the luminaire when mated with Endurance N control bases

### APPLICATIONS

- Street and area lighting
- Roadway lighting
- Commercial outdoor lighting  
(i.e. parking lots, car dealerships)
- Photo controls

# LUMAWISE Endurance N ANSI C136.10 Receptacle Assembly

## ELECTRICAL

- Power contacts  
Current rating: 15 A max  
Voltage rating: 480 VAC/DC
- cUR recognized to UL 773

## MECHANICAL


- Conforms to dimensional requirements of ANSI C136.10
- Power contacts terminated to 14AWG stranded wire per UL1015 or UL3321

## MATERIALS

- Power contacts: Copper alloy, tin over nickel plating
- Housing: Glass filled PBT, UL 94V-0 flammability rated


## SPECIFICATIONS

- Product: **108-32059**
- Application: **114-32115/114-32148**

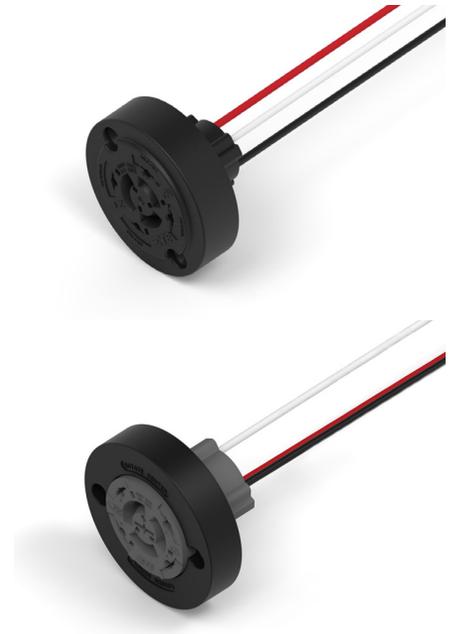

## PRODUCT INFORMATION

Description	Position	Wire	Part Number
Standard Receptacle Assembly	3	150 °C	<b>6-2213362-2</b>
		105 °C	<b>6-2213362-1</b>
Rotatable Receptacle Assembly	3	150 °C	<b>2213848-1</b>
		105 °C	<b>2213848-2</b>

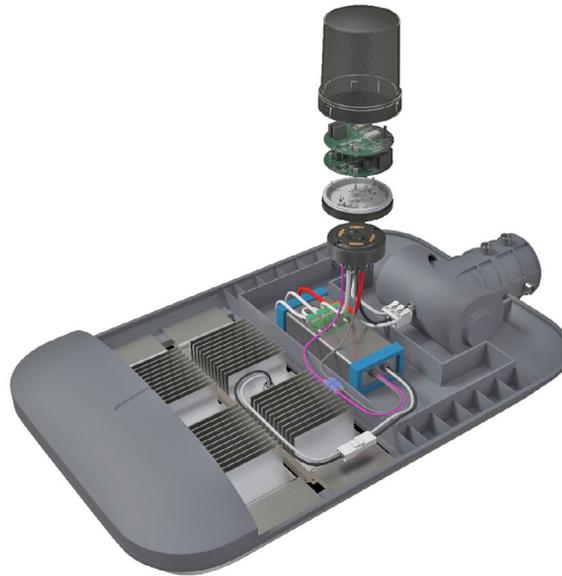

## te.com

LUMAWISE, TE Connectivity, TE Connectivity (logo) and Every Connection Counts are trademarks. All other logos, products and/or company names referred to herein might be trademarks of their respective owners.

While TE has made every reasonable effort to ensure the accuracy of the information in this brochure, TE does not guarantee that it is error-free, nor does TE make any other representation, warranty or guarantee that the information is accurate, correct, reliable or current. TE reserves the right to make any adjustments to the information contained herein at any time without notice. TE expressly disclaims all implied warranties regarding the information contained herein, including, but not limited to, any implied warranties of merchantability or fitness for a particular purpose. The dimensions in this catalog are for reference purposes only and are subject to change without notice. Specifications are subject to change without notice. Consult TE for the latest dimensions and design specifications.

© 2019 TE Connectivity. All Rights Reserved.

8-1773982-5 02/20 ML Original