

Bundling and Securing

Clamps


Plastic P-Clamps

HP-Series

HellermannTyton P-Clamps easily guide and locate wires and cables. The clamps are designed with radius edges to prevent chafing and cutting into insulation. Available sizes up to 1" bundle diameters.

Features and Benefits

- P-Clamps easily guide and locate wire and cables up to 1" in diameter.
- Designed with a radius edge to prevent chafing and cutting into insulation.

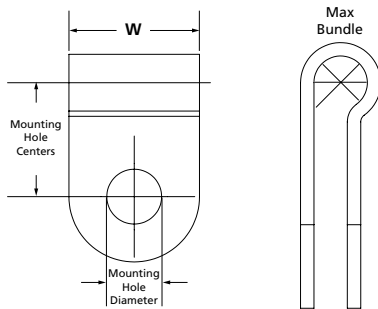

PART NO.	TYPE	Max. Bundle Diameter in. (mm)	Width (W) in. (mm)	Mounting Hole Centers in. (mm)	Mounting Hole Dia. in. (mm)	Material	Color	Pkg. Qty.
211-60019	H1P	0.1 (3.2)	0.4 (10.0)	0.3 (8.5)	0.2 (4.2)	PA66	Natural	1000
211-00261		0.1 (3.2)	0.4 (10.0)	0.3 (8.5)	0.2 (4.2)	PA66	Natural	100
211-60010		0.1 (3.2)	0.4 (10.0)	0.3 (8.5)	0.2 (4.2)	PA66HS	Black	1000
211-60000		0.1 (3.2)	0.4 (10.0)	0.3 (8.5)	0.2 (4.2)	PA66HS	Black	100
211-60029	H2P	0.2 (5.0)	0.4 (10.0)	0.4 (9.5)	0.2 (4.2)	PA66	Natural	1000
211-00263		0.2 (5.0)	0.4 (10.0)	0.4 (9.5)	0.2 (4.2)	PA66	Natural	100
211-60001		0.2 (5.0)	0.4 (10.0)	0.4 (9.5)	0.2 (4.2)	PA66HS	Black	100
211-00262		0.2 (5.0)	0.4 (10.0)	0.4 (9.5)	0.2 (4.2)	PA66HS	Black	1000
211-60039	H3P	0.3 (6.5)	0.4 (10.0)	0.4 (10.0)	0.2 (4.2)	PA66	Natural	1000
211-00264		0.3 (6.5)	0.4 (10.0)	0.4 (10.0)	0.2 (4.2)	PA66	Natural	100
211-60040		0.3 (6.5)	0.4 (10.0)	0.4 (10.0)	0.2 (4.2)	PA66HS	Black	1000
211-60002		0.3 (6.5)	0.4 (10.0)	0.4 (10.0)	0.2 (4.2)	PA66HS	Black	100
211-60049	H4P	0.3 (8.0)	0.4 (10.0)	0.4 (10.0)	0.2 (4.2)	PA66	Natural	1000
211-60050		0.3 (8.0)	0.4 (10.0)	0.4 (10.0)	0.2 (4.2)	PA66HS	Black	1000
211-60003		0.3 (8.0)	0.4 (10.0)	0.4 (10.0)	0.2 (4.2)	PA66HS	Black	100
211-00266	H5P	0.4 (9.5)	0.4 (10.0)	0.4 (11.0)	0.2 (4.2)	PA66	Black	1000
211-60059		0.4 (9.5)	0.4 (10.0)	0.4 (11.0)	0.2 (4.2)	PA66	Natural	1000
211-00267		0.4 (9.5)	0.4 (10.0)	0.4 (11.0)	0.2 (4.2)	PA66	Natural	100
211-60004		0.4 (9.5)	0.4 (10.0)	0.4 (11.0)	0.2 (4.2)	PA66HS	Black	100
211-60061	H6P	0.4 (11.0)	0.4 (10.0)	0.5 (13.0)	0.2 (4.2)	PA66HS	Black	1000
211-60005		0.4 (11.0)	0.4 (10.0)	0.5 (13.0)	0.2 (4.2)	PA66HS	Black	100

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.

Plastic P-Clamps

HP-Series

PART NO.	TYPE	Max. Bundle Diameter in. (mm)	Width (W) in. (mm)	Mounting Hole Centers in. (mm)	Mounting Hole Dia. in. (mm)	Material	Color	Pkg. Qty.
211-60079	H7P	0.5 (12.5)	0.4 (10.0)	0.6 (14.0)	0.2 (4.2)	PA66	Natural	1000
211-00269		0.5 (12.5)	0.4 (10.0)	0.6 (14.0)	0.2 (4.2)	PA66	Natural	100
211-60078		0.5 (12.5)	0.4 (10.0)	0.6 (14.0)	0.2 (4.2)	PA66HS	Black	1000
211-60006		0.5 (12.5)	0.4 (10.0)	0.6 (14.0)	0.2 (4.2)	PA66HS	Black	100
211-60089	H8P	0.6 (14.0)	0.4 (10.0)	0.6 (15.0)	0.2 (4.2)	PA66	Natural	1000
211-60090		0.6 (14.0)	0.4 (10.0)	0.6 (15.0)	0.2 (4.2)	PA66HS	Black	1000
211-60007		0.6 (14.0)	0.4 (10.0)	0.6 (15.0)	0.2 (4.2)	PA66HS	Black	100
211-60099	H9P	0.6 (16.0)	0.4 (10.0)	0.6 (16.0)	0.2 (4.2)	PA66	Natural	1000
211-00271		0.6 (16.0)	0.4 (10.0)	0.6 (16.0)	0.2 (4.2)	PA66	Natural	100
211-60008		0.6 (16.0)	0.4 (10.0)	0.6 (16.0)	0.2 (4.2)	PA66HS	Black	100
211-60009	H10P	0.7 (17.5)	0.4 (10.0)	0.7 (17.0)	0.2 (4.2)	PA66HS	Black	100
211-60130	H12P	0.8 (20.5)	0.4 (10.0)	0.8 (19.0)	0.2 (4.2)	PA66HS	Black	1000
211-60140	H13P	0.9 (22.0)	0.5 (12.0)	0.8 (20.5)	0.2 (5.2)	PA66HS	Black	1000
211-60150	H14P	1.0 (24.0)	0.5 (12.0)	0.9 (21.5)	0.2 (5.2)	PA66HS	Black	1000
211-60160	H15P	1.0 (25.5)	0.5 (12.0)	0.9 (23.0)	0.2 (5.2)	PA66HS	Black	1000

Dimensions are approximate and subject to technical changes. Use Part No. for ordering and Type for specification purposes.