


# 150520 Series

## In-Line Fuseholders for 5×20mm Fuses

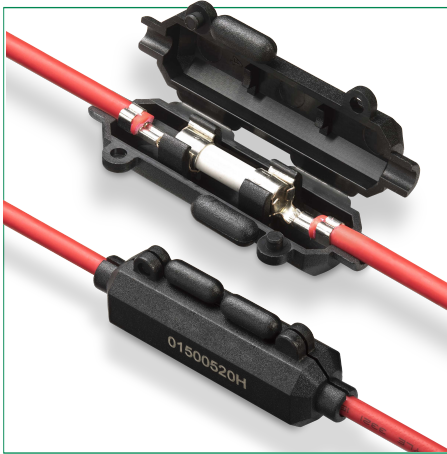

### Description

The 150520 In-Line fuseholder is rated at 600 VAC/VDC ideal for applications where supplemental protection is needed, such as lighting ballasts and power supplies. 8-inch pre-stripped wire leads and fuse clips come preassembled for quick installation.

### Features/Benefits

- High voltage rating accommodates many power applications
- Wire leads are pre-attached to fuse clips for quick assembly
- Single piece molded body
- UL Recognized to UL/CSA 4248.1

### Additional Information



Resources



Accessories



Samples

### Agency Approval

Agency	Agency File Number
UL US	TBD

### Specifications


<b>Voltage Rating</b>	600 VAC/VDC
<b>Ampere Rating</b>	20 A
<b>Fuse Type</b>	5 X 20 mm
<b>Fuse Clips</b>	Tin-plated brass
<b>Wire</b>	14 AWG UL3321, XLPE Insulated, Red Color
<b>Molded Body</b>	Single piece thermoplastic
<b>Flammability Rating</b>	UL94 V-0
<b>Environmental</b>	RoHS compliant and Pb free
<b>Storage Temperature</b>	-40°C to 80°C
<b>Operating Temperature</b>	-40°C to 105°C
<b>Ingress Protection</b>	IP40

**Note:** Refer to [Fuseology](#) for information on proper fuseholder re-rating.

### Ordering Information

Ordering Number	Packaging
01500520H	Bulk Pack (100 Pcs)

### Dimensions [mm]

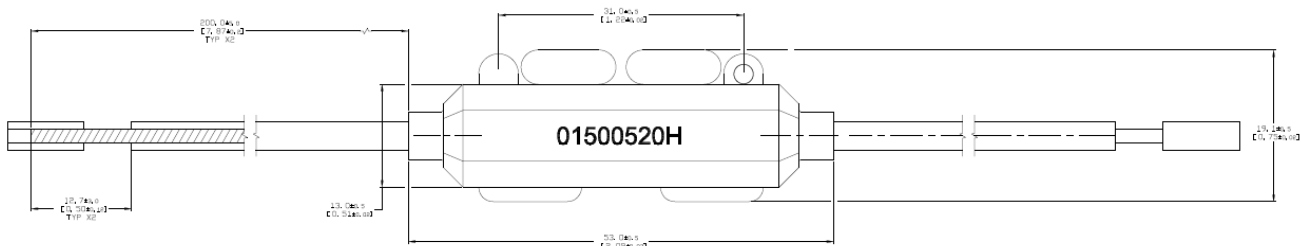

**Warning:** Electrical Shock. Power must be disconnected prior to handling fuse.

**Disclaimer Notice** - Information furnished is believed to be accurate and reliable. However, users should independently evaluate the suitability of and test each product selected for their own applications. Littelfuse products are not designed for, and may not be used in, all applications. Read complete Disclaimer Notice at: [www.littelfuse.com/disclaimer-electronics](http://www.littelfuse.com/disclaimer-electronics).