

FEATURES

12VDC




IP67 Waterproof

160° Wide Beam

50 Modules Per Strand

3M Tape Mounting

MINI LED SIGN MODULE

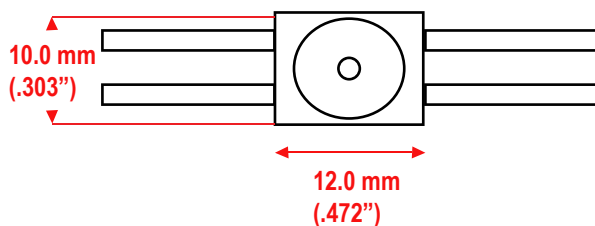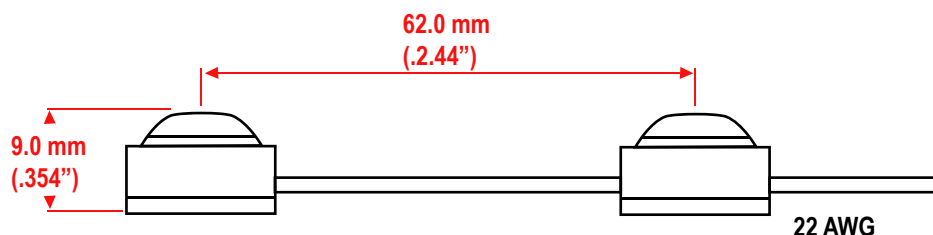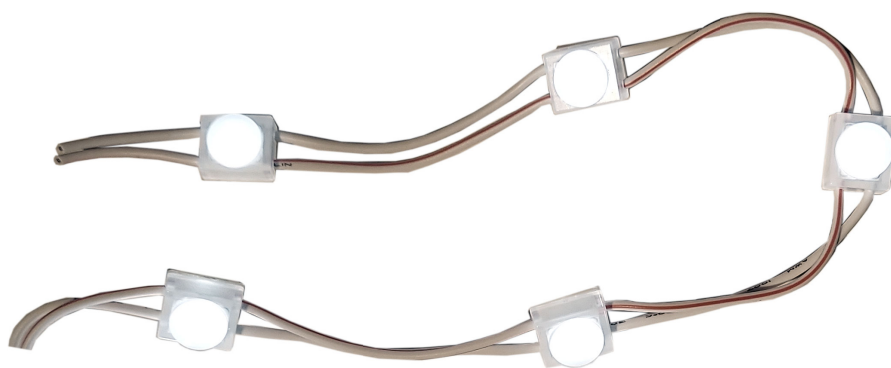

Module Material
Body: ABS, UL94-0
Lens: Polycarbonate

JKL Part Number	Input Voltage	Power per Module	CCT	Beam Angle	Lumen Flux Per Module	Modules Per Strand
ZM-129-CW	12VDC	0.36 W	6,000°K	160°	33	50

THERMAL:

Operating Temperature: -20°C ~ 50°C

Storage Temperature: -20°C ~ 60°C

NOTES:

- Mounting can be accomplished with double sided tape that is on the backside of the modules.
- Wire with Red Stripe is Positive Input.
- Use no more than 50 modules per run. If more modules are required, use another run in parallel to connect more.
- Take care to prevent exposed wires on the ends.

			METRIC		DIMENSIONS ARE IN mm (INCHES)		JKL COMPONENTS CORPORATION			
			THIRD ANGLE PROJECTION		TOLERANCE UNLESS OTHERWISE SPECIFIED 1 PL +/- REF. 2 PL +/- REF. ANGLE +/-		TITLE MINI LED SIGN MODULE			
			DRAWN BY S Newton		APP'D BY DATE JV 4/21/23		SIZE A		FSCM NO. 55335	
			Released		4/21/23		DRAWING NO. ZM-129-CW			
REV. NO.			DESCRIPTION/ECO NUMBER		APP'D DATE		SCALE NONE		RELEASED DATE 4/21/23	
							REVISION		REV. NO.	
									SHEET 1 OF 1	