


Mates With:
GPC

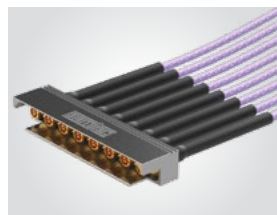

Some sizes, styles and options are non-standard, non-returnable.

SERIES	NO. OF ROWS	NO. OF POSITIONS	ASSEMBLY LENGTH
GC47 = Ganged SMPM with (1.2 mm) .047" overshield DIA 29 AWG millimeter wave cable	-1	-02, -04, -06, -08, -10	-"XXXX" = Assembly Length in millimeters -0100 (100 mm) 3.94" minimum

NO. OF POSITIONS	A	B
-02	(8.89) .350	(3.56) .140
-04	(16.00) .630	(10.67) .420
-06	(22.10) .870	(17.78) .700
-08	(30.23) 1.190	(24.89) .980
-10	(37.34) 1.470	(32.00) 1.260

OAL = Assembly Length

(3.56) .140

B

(7.04) .277

GC47-1-08-XXXX SHOWN

Mates With:
GC47, GC86



Notes:
Some sizes, styles and options are non-standard, non-returnable.